

Navigator 600 Silica Analyzers – Spare Parts




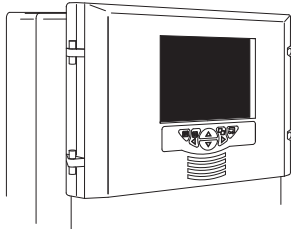
1 Introduction



 

This list contains part numbers and illustrations for Navigator Silica analyzers spare parts.





 
 

2 Spare Parts


 


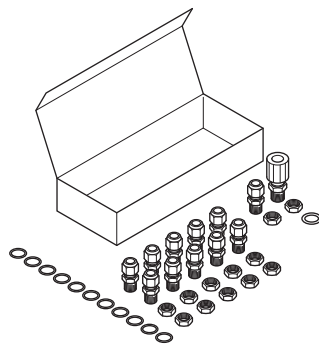
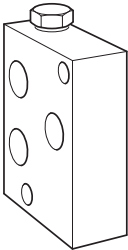






 
 
Warning. Spares items identified with this symbol should only be fitted by personnel from ABB or its approved representative(s).

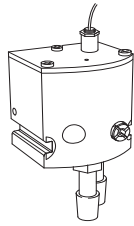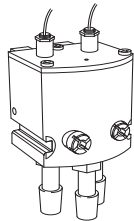



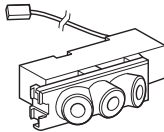Part No.	Description
AW600 023	Cable gland kit 
AW600 025	Primary debubbler 
AW600 028	Electronics section (excluding PSU and Profibus card)  

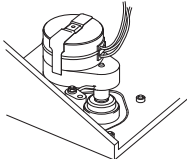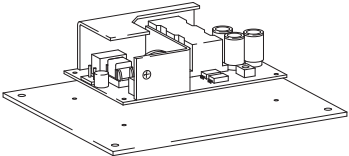

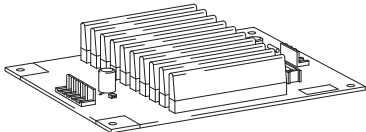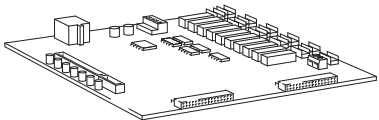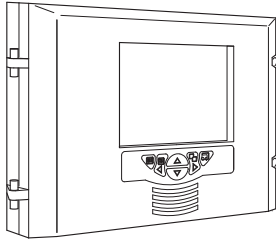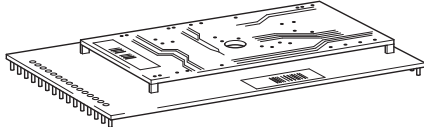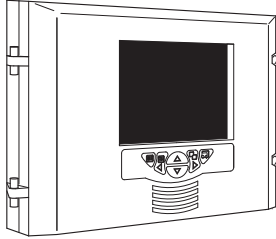

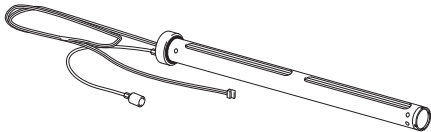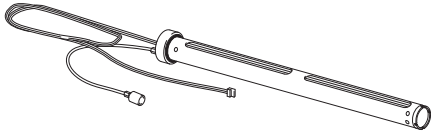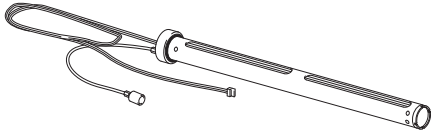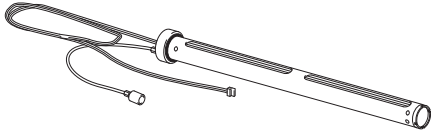
Part No.	Description
AW600 030	Single-stream constant-head unit 
AW600 031	Multi-stream constant-head unit (single block shown) 
AW600 032	Sample selector valve (including seal) 
AW600 033	Out-of-sample switch 

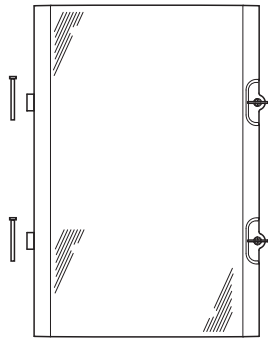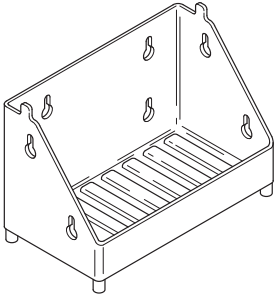

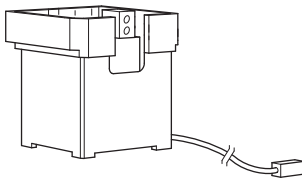
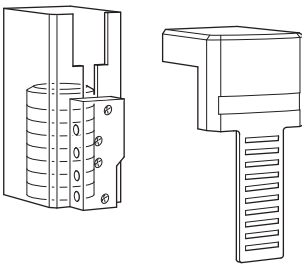
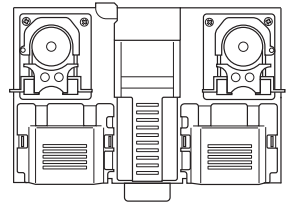
Part No.	Description
AW600 034	Solenoid valve replacement (including manifold) 
AW600 045	Heater 
AW600 046	Pt1000 Temperature sensor 
AW600 047	Pump motor assembly (including coupling) 
AW600 048	Connection board PCB 
AW600 049	Filter assembly 
AW600 051	AW600 PSU kit – AC 

Part No.	Description
AW600 056	AW600 PSU kit – DC 
AW600 061	Secondary debubbler assembly (cuvette) 
AW600 065	Application board assembly 
AW600 066	Front door assembly with membrane keypad (excluding display) 
AW600 067	Profibus PCB assembly (option) 
AW600 068	Front door assembly with membrane keypad plus display 

Part No.	Description
AW601 069	Level sensor – red (2.5 l – reagent 1) 
AW600 071	Level sensor – violet (2.5 l – reagent 2) 
AW601 072	Level sensor – orange (2.5 l – reagent 3) 
AW600 073	Level sensor – brown (2.5 l – reagent 4) 
AW600 075	Level sensor – light grey (0.5 l cleaning) 
AW600 076	Level sensor – yellow (0.5 l secondary calibration) 

Part No.	Description
AW600 085	Main case door assembly (including pins) 
AW600 157	Reagent shelf 
AW601 051	Bottle – ammonium molybdate, violet (reagent 2 – 2.5 l) 
AW600 062	Bottle – secondary calibration, yellow (500 ml) 

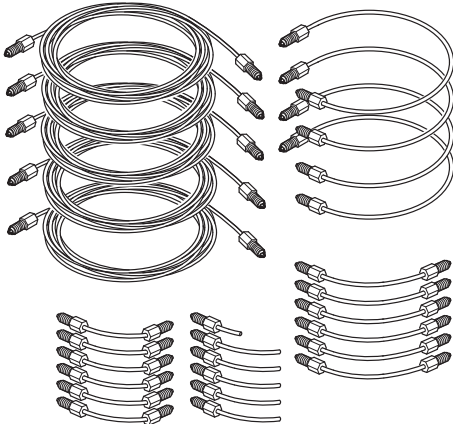Part No.	Description
AW600 063	Bottle – cleaning solution, light grey (500 ml) 
AW601 071	Bottle – 1 st acid sulphuric, red (reagent 1, 2.5 l) 
AW601 076	Bottle – 2 nd acid sulphuric and citric, orange (reagent 3, 2.5 l) 
AW600 081	Bottle – reduction ascorbic, brown (reagent 4, 2.5 l) 
AW601 100	Tube replacement kit (excluding pump tubes – see AW601 116/117/118/119 on page 5) 

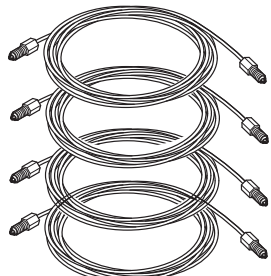Part No.	Description
AW601 102	Reagent tube (only) replacement kit 
AW600 087	Filter pack 
AW600 091	Optical unit (including secondary debubbler) 
AW601 112	Reaction coil assembly (including cover) 
AW601 113	Complete wet section 

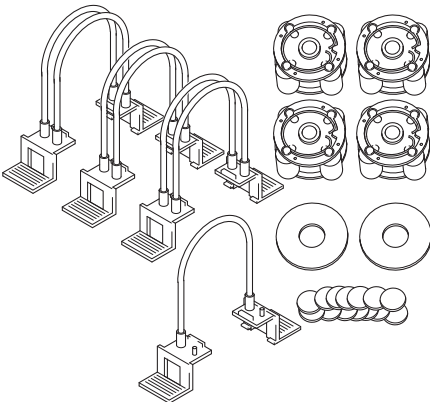
 
 
 
 
Part No.	Description
AW601 115	Annual pump spares kit, see IM/NAV6S for details 
AW600 096	Replacement pump tube (blue, green) 
AW600 097	Replacement pump tube (grey) 
AW601 118	Replacement pump tube (red, violet) 
AW601 119	Replacement pump tube (orange, brown) 

ABB has Sales & Customer Support expertise
in over 100 countries worldwide

www.abb.com

The Company's policy is one of continuous product
improvement and the right is reserved to modify the
information contained herein without notice.

Printed in UK (10.09)

© ABB 2009



ABB Limited
Oldends Lane, Stonehouse
Gloucestershire
GL10 3TA
UK
Tel: +44 (0)1453 826661
Fax: +44 (0)1453 829671

ABB Inc.
125 E. County Line Road
Warminster
PA 18974
USA
Tel:+1 215 674 6000
Fax:+1 215 674 7183