



SACE Tmax XT

FC CuAl - Terminali anteriori per cavi in rame - alluminio XT1-XT2-XT3-XT4
 FC CuAl - Front terminals for copper-aluminum cables XT1-XT2-XT3-XT4
 FC CuAl - Vorderseitige Anschlüsse für Kabel aus Kupfer - Aluminium XT1-XT2-XT3-XT4
 FC CuAl - Prises avant pour câbles en cuivre - aluminium XT1-XT2-XT3-XT4
 FC CuAl - Terminales frontales para cables de cobre - aluminio XT1-XT2-XT3-XT4

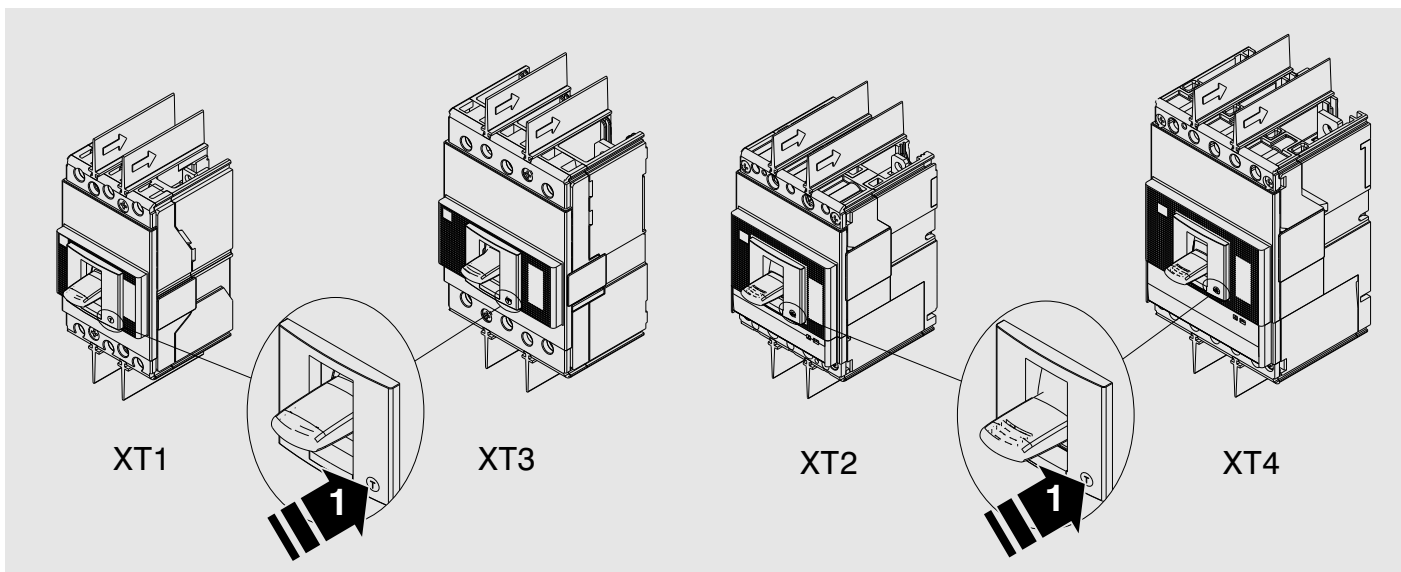


F-P-W	XT1	III	3 (6)	/	/	/	3(6)	/	3(6) 3(6)
		IV	4 (8)	/	/	/	4(8)	/	4(8) 4(8)
	XT2	III	/	3(6)	/	/	/	3(6)	/ /
		IV	/	4(8)	/	/	/	4(8)	/ /
	XT3	III	/	3(6)	3(6)	3(6)	/	3(6)	3(6) 3(6)
		IV	/	4(8)	4(8)	4(8)	/	4(8)	4(8) 4(8)
	XT4	III	/	3(6)	/	/	/	3(6)	/ /
		IV	/	4(8)	/	/	/	4(8)	/ /


A XT1-XT2-XT3-XT4

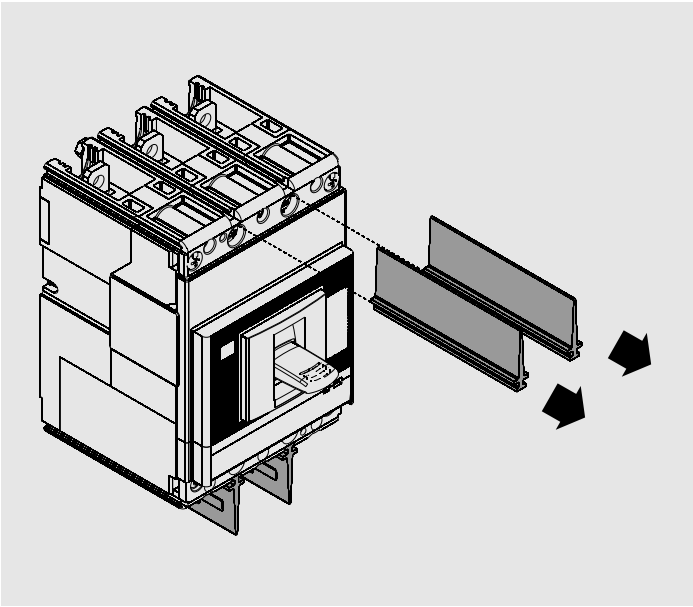


B XT1

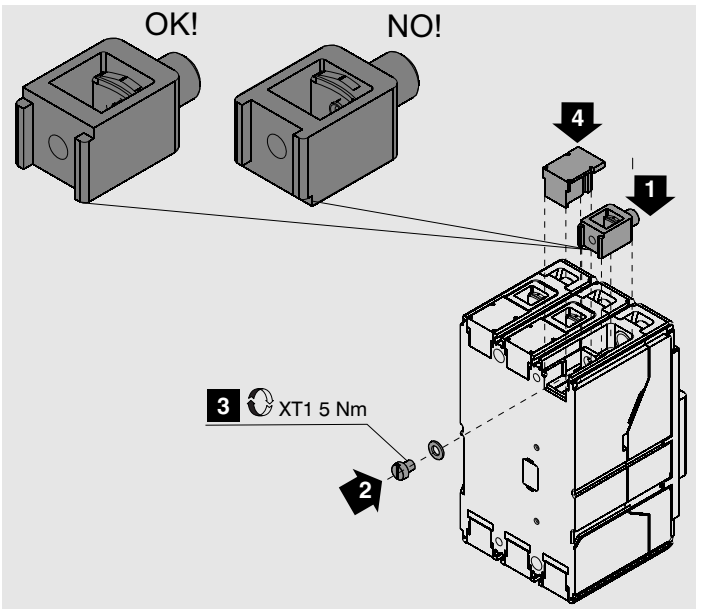


C XT2-XT3-XT4

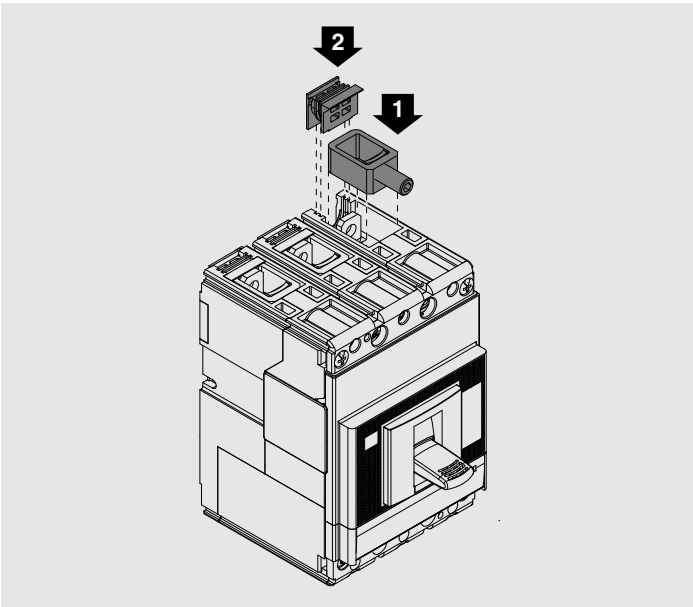

D XT3

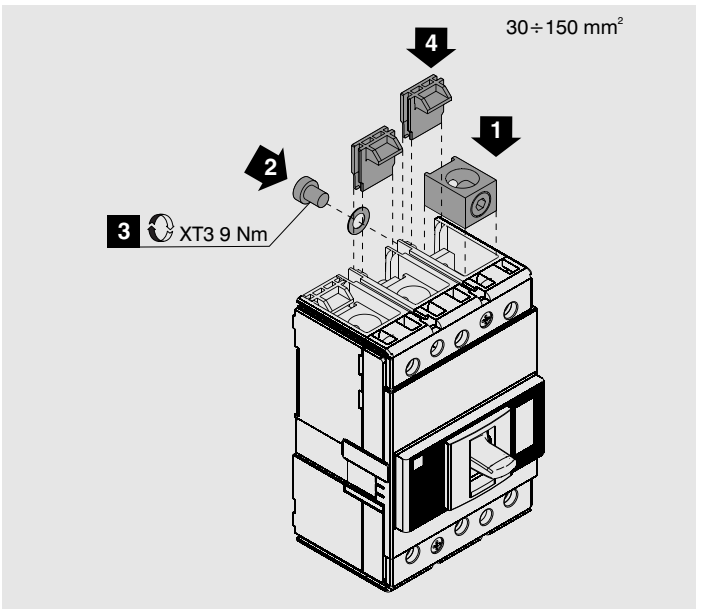

E XT1-XT2-XT3-XT4

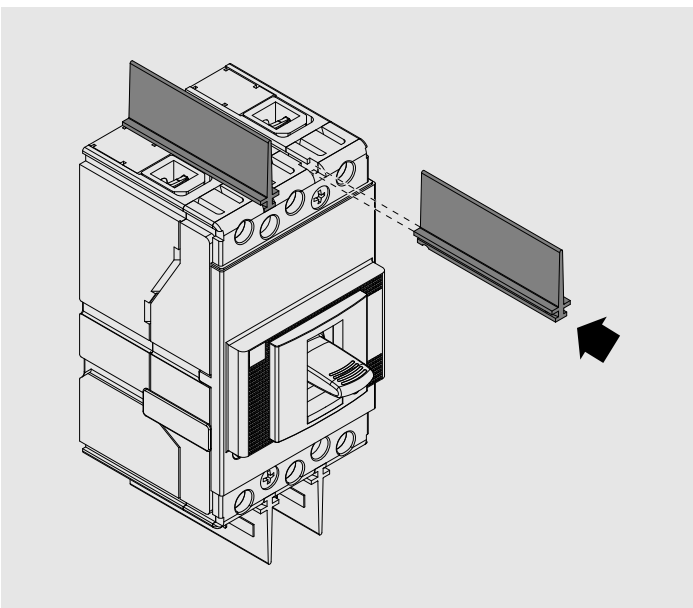

F XT1-XT2-XT3-XT4

	XT1	XT2	XT3	XT4
A	9,5	14	17	17
B	16	14	20	21

	30-150 mm²	90-185 mm²
XT1	MAX 50 mm² MIN 1,5 mm²	MAX 50 mm² MIN 1,5 mm²
XT2	MAX 95 mm² MIN 2,5 mm²	MAX 70 mm² MIN 2,5 mm²
XT3	MAX 185 mm² MIN 90 mm²	
XT3	MAX 150 mm² MIN 30 mm²	
XT4	MAX 185 mm² MIN 2,5 mm²	MAX 150 mm² MIN 2,5 mm²

XT1	7 Nm
XT2	7 Nm
XT3	16 Nm (30-150 mm²) 31 Nm (90-185 mm²)
XT4	10 Nm


G

XT1-XT2-XT3-XT4

P-W	XT1	III	2(4)	1(2)	/
		IV	2(4)	/	1(2)
	XT2	III	2(4)	1(2)	/
		IV	2(4)	/	1(2)
	XT3	III	2(4)	1(2)	/
		IV	2(4)	/	1(2)
	XT4	III	2(4)	1(2)	/
		IV	2(4)	/	1(2)


H

XT1-XT2-XT3-XT4

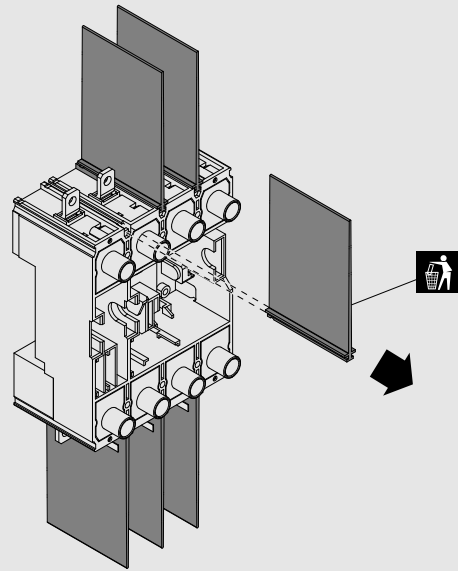


I

XT1-XT2-XT3-XT4

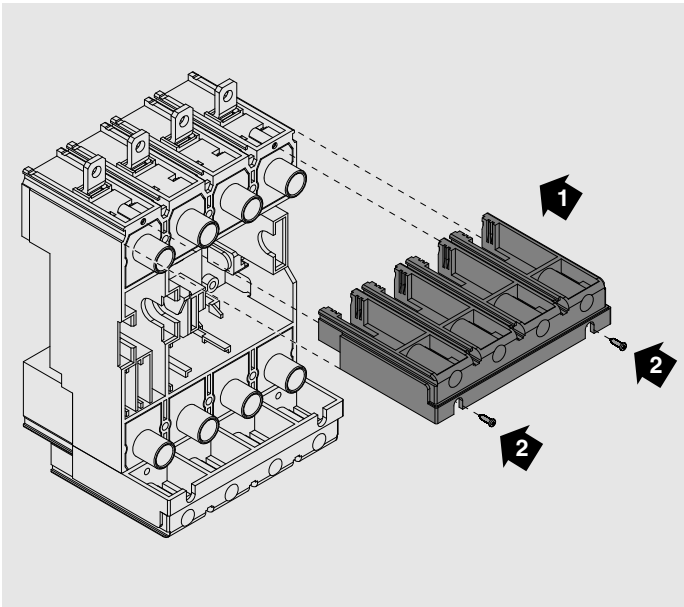


J

XT1

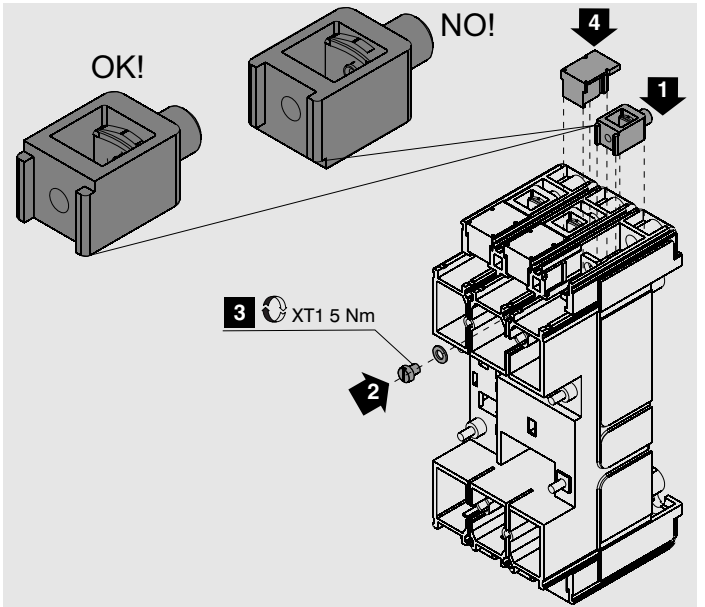


K

XT3

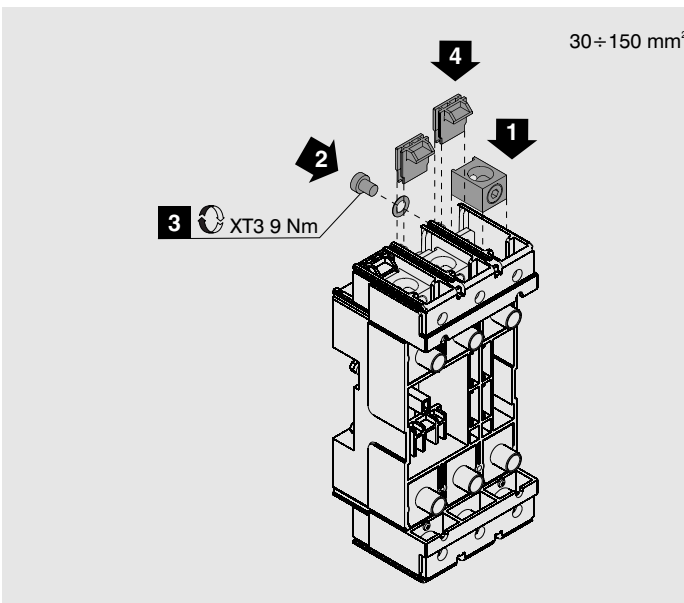


L

XT2-XT3-XT4

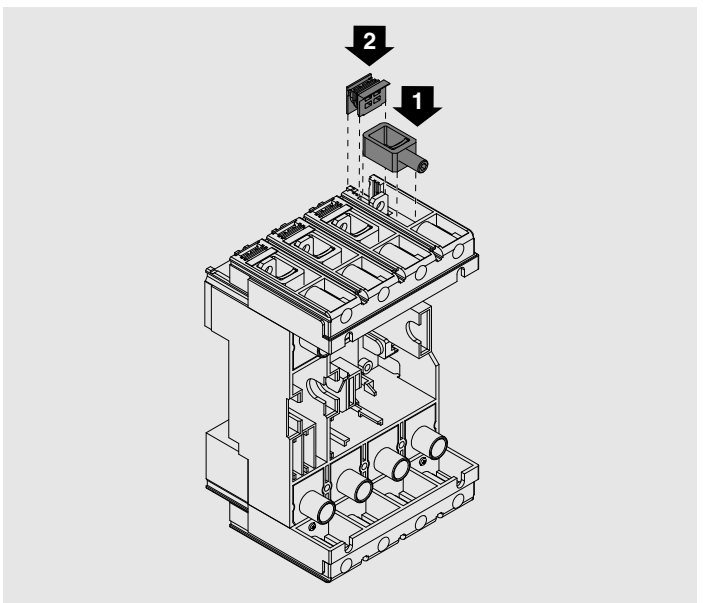

K

XT1-XT2-XT3-XT4

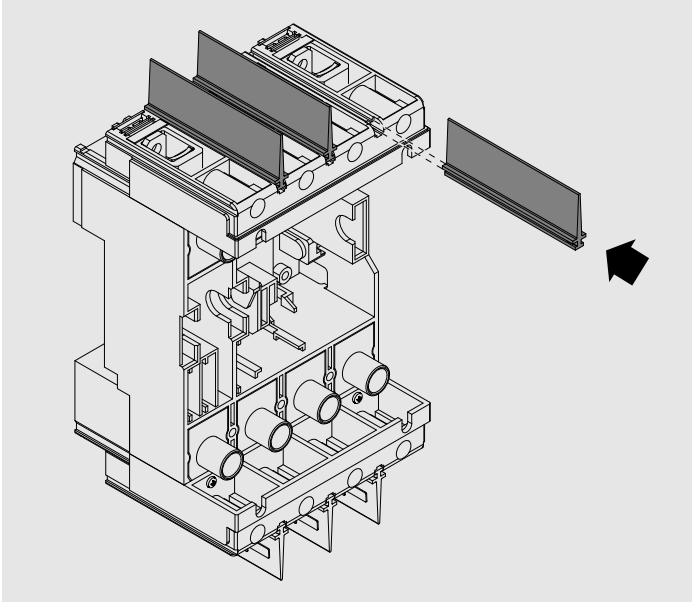

L

XT1-XT2-XT3-XT4

	XT1	XT2	XT3		XT4
A	9,5	14	30-150	90-185	17
B	16	14	20	20	21

	XT1	XT2	XT3	XT4
MAX	50 mm ²	70 mm ²	185 mm ²	150 mm ²
MIN	1,5 mm ²	2,5 mm ²	30 mm ²	2,5 mm ²

XT1	7 Nm
XT2	7 Nm
XT3	16 Nm
XT4	10 Nm

For more information please contact:

ABB S.p.A.
 ABB SACE Division
 Via Baioni, 35
 24123 Bergamo - Italy
 Phone: +39 035 395 111
 Fax: +39 035 395 306 - 433

www.abb.com