

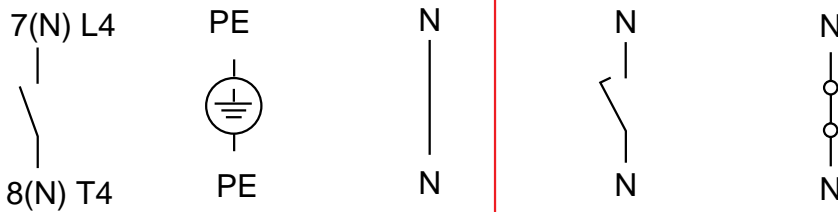


OTPS 32EP OTPE 32EP OTPN 32EP OTPL 32EP OTPD 32EP

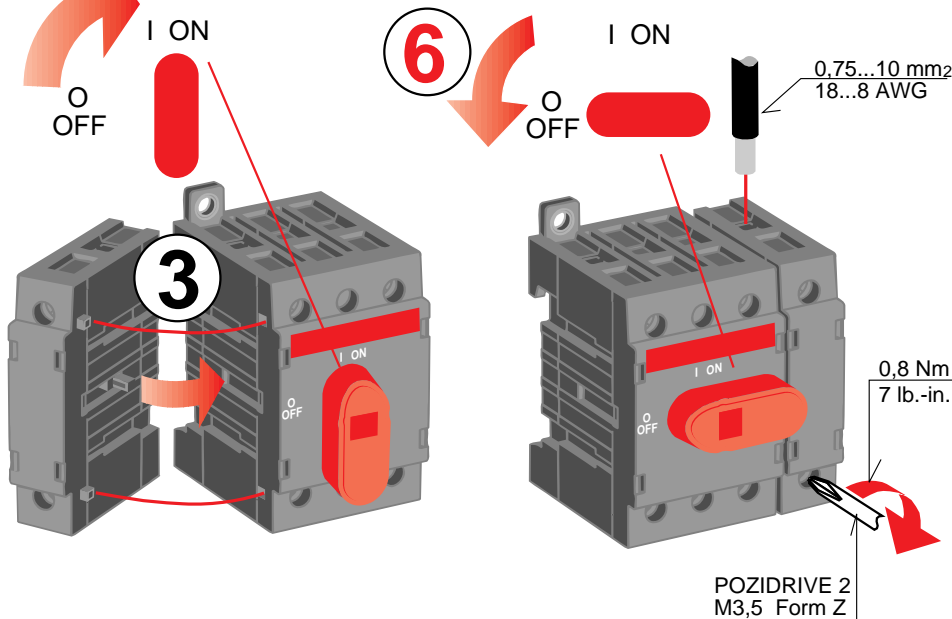


OT16E3, OT25E3, OT32E3

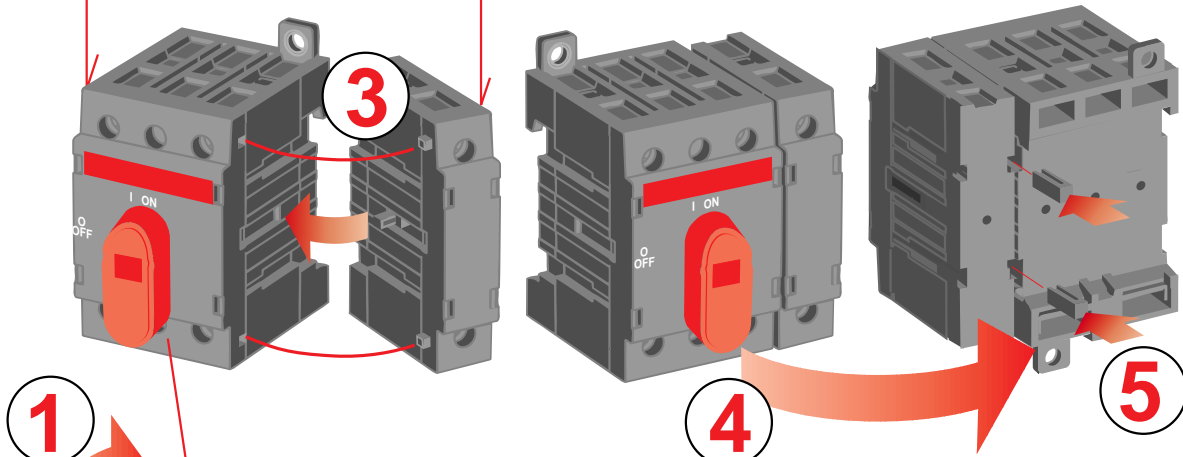


UL not completed
CSA not completed
OTPL 32EP
OTPD 32EP

CSA LR 58077
Certified for use with
OT16E3, OT25E3, OT32E3





UL IND.CONT.
EQ 3E73
General Use Ratings
600 VAC 40 A
Listed for use with
OT16E3, OT25E3, OT32E3

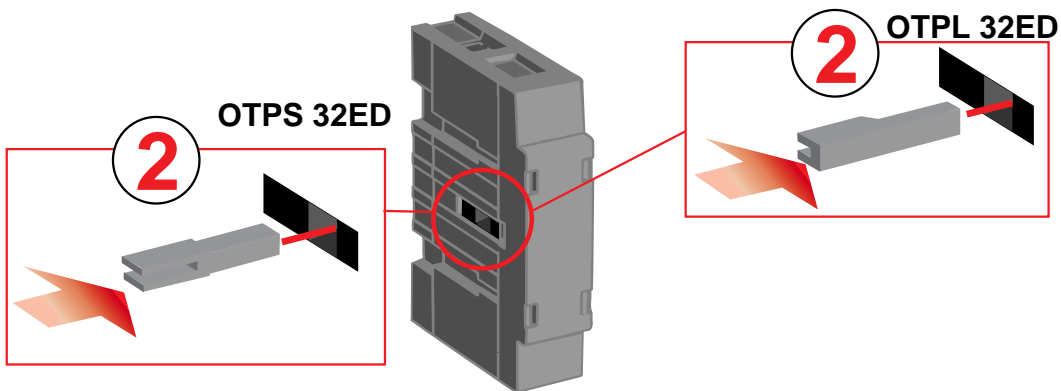

OTPS 32ED OTPE 32ED OTPN 32ED OTPL 32ED

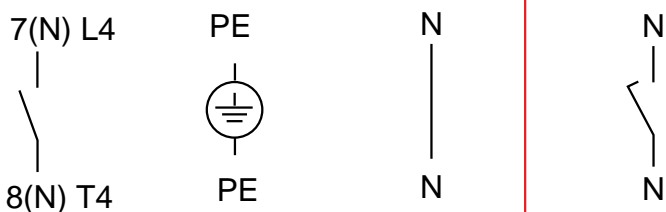

OT16ET3, OT25ET3, OT32ET3

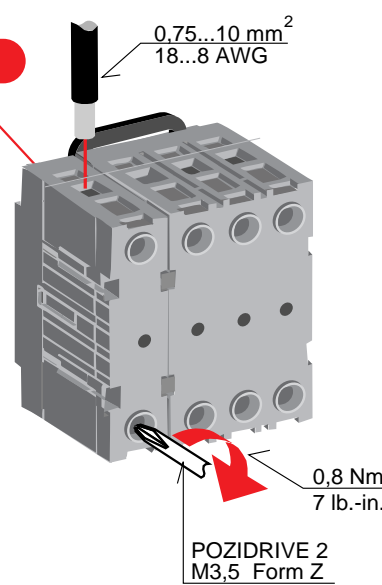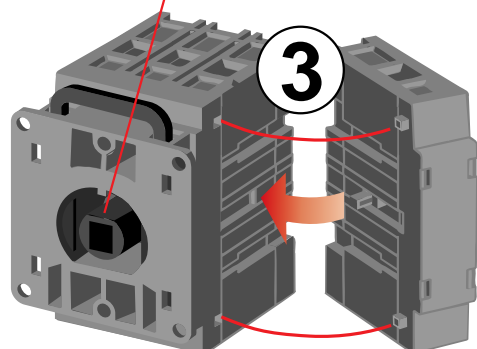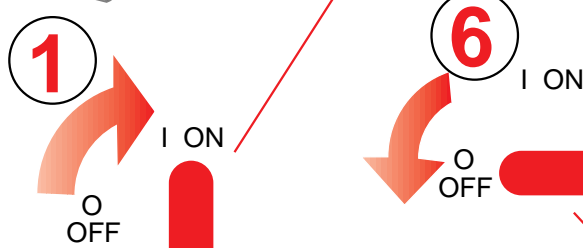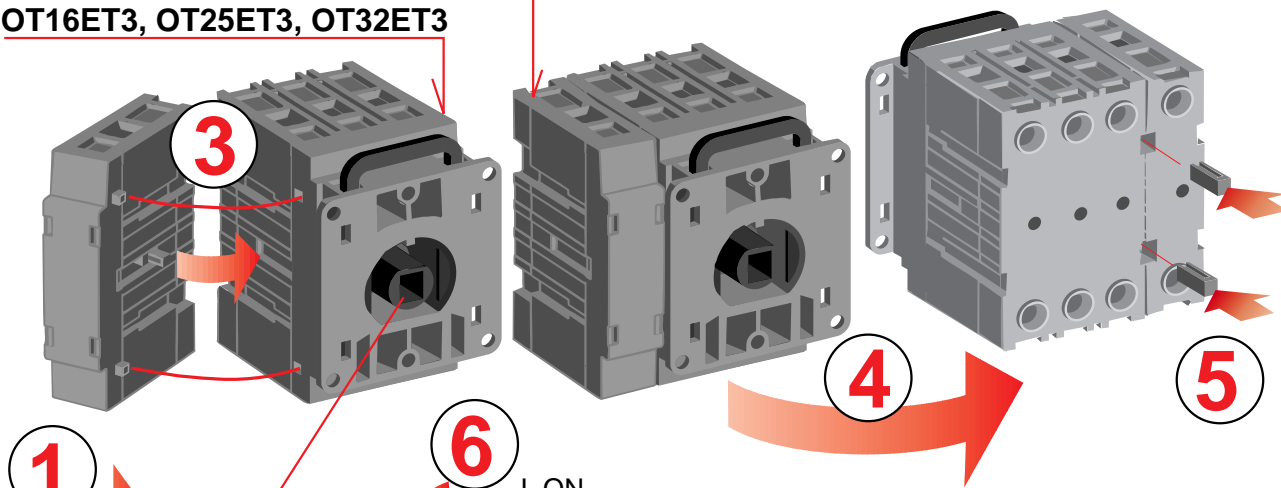

UL not completed
CSA not completed
OTPL 32ED

CSA LR 58077
Certified for use with
OT16ET3, OT25ET3, OT32ET3

UL IND.CONT. EQ 3E73
General Use Ratings
600 VAC 40 A
Listed for use with
OT16ET3, OT25ET3, OT32ET3