



EC DECLARATION OF CONFORMITY

(supplier's name) We ABB SACE S.p.A

(address) VIALE VICENZA, 61

36063 - MAROSTICA (VI)

declare under our sole responsibility that the product : _____

MINI - TRUNKINGS - 01 SERIES

(name, type or model, lot, batch or serial number, possibly sources and numbers of items)

ARTICLES : IN ATTACHED

to which this declaration relates is in conformity with the following standard(s) or other
normative/documents CEI 23-32

RELEASE FROM IMQ INSTITUTE BY D.A.T. N° E7157

(title and/or number and date of issue of the standard(s) or other normative document(s))

following the provisions of the Directive(s) 73/23 CEE MODIFIED BY 93/68 CEE

MAROSTICA, 11/03/2002

(Place and date of issue)

02

(last two digits of the year in which the mark was affixed)

ABB SACE S.p.A
TECHNICAL MANAGER
ENZO RIZZI

(seal, name and signature of authorized person)

Mod. 379 - 12/94 - 900

1SLT000001D00

Mini-trunkings

Equipped mini-trunkings



Article	Dimensions WxH (mm)	Compartments	Colour	Unit/pack-metres
---------	---------------------	--------------	--------	------------------

Mini-trunking with standard cover

41 080	20x10 [IMQ]	1	White	96
41 081	20x10 [IMQ]	2	White	96
41 083	30x10 [IMQ]	1	White	64
41 084	30x10 [IMQ]	2	White	64
41 110	15x17 [IMQ]	1	White	92
41 091	30x17 [IMQ]	1	White	72
41 092	40x17 [IMQ]	2	White	48
41 093	60x17 [IMQ]	3	White	36
41 117	25x30 [IMQ]	1	White	60
41 119	40x30 [IMQ]	1	White	40
01 160	15x17 [IMQ]	1	Grey	92
01 180	15x17 [IMQ]	1	Brown	92

Mini-trunking with adhering cover*

41 101	20x10 [IMQ]	1	White	96
41 102	20x10 [IMQ]	2	White	96
41 103	30x10 [IMQ]	1	White	64
41 104	30x10 [IMQ]	2	White	64
41 106	40x10 [IMQ]	2	White	48
41 111	15x17 [IMQ]	1	White	92
41 113	30x17 [IMQ]	1	White	72
41 114	30x17 [IMQ]	1	White	72
41 115	40x17 [IMQ]	2	White	48
41 116	60x17 [IMQ]	3	White	36
41 120	60x30 [IMQ]	3	White	34
01 151	20x10 [IMQ]	1	Grey	96
01 163	30x17 [IMQ]	1	Grey	72
01 171	20x10 [IMQ]	1	Brown	96
01 183	30x17 [IMQ]	1	Brown	72

* Special tool required for removing covers

Article	Trunking dimensions WxH (mm)	Colour	Unit/pack-pieces
---------	------------------------------	--------	------------------

Adjustable flat corner

41 202	20x10 [IMQ]	White	40
41 204	30x10 [IMQ]	White	40
41 206	40x10 [IMQ]	White	40
41 210	15x17 [IMQ]	White	40
41 213	30x17 [IMQ]	White	40
41 215	40x17 [IMQ]	White	40
41 216	60x17 [IMQ]	White	20
41 217	25x30 [IMQ]	White	40
41 219	40x30 [IMQ]	White	20
41 220	60x30 [IMQ]	White	10
01 252	20x10 [IMQ]	Grey	40
01 260	15x17 [IMQ]	Grey	40
01 263	30x17 [IMQ]	Grey	40
01 272	20x10 [IMQ]	Brown	40
01 280	15x17 [IMQ]	Brown	40
01 283	30x17 [IMQ]	Brown	40

Mini-trunkings

Equipped mini-trunkings

2



FLCPR023



FLCPR024



FLCPR025

Article	Trunking dimensions WxH (mm)	Colour	Unit/pack – pieces
---------	------------------------------	--------	--------------------

Flat tee branch

41 302	20x10 [IMQ]	White	40
41 304	30x10 [IMQ]	White	40
41 306	40x10 [IMQ]	White	40
41 310	15x17 [IMQ]	White	40
41 313	30x17 [IMQ]	White	40
41 315	40x17 [IMQ]	White	40
41 316	60x17 [IMQ]	White	40
41 317	25x30 [IMQ]	White	40
41 319	40x30 [IMQ]	White	40
41 320	60x30 [IMQ]	White	20
01 352	20x10 [IMQ]	Grey	40
01 360	15x17 [IMQ]	Grey	40
01 363	30x17 [IMQ]	Grey	40
01 372	20x10 [IMQ]	Brown	40
01 380	15x17 [IMQ]	Brown	40
01 383	30x17 [IMQ]	Brown	40

Adjustable internal corner


41 402	20x10 [IMQ]	White	40
41 404	30x10 [IMQ]	White	40
41 406	40x10 [IMQ]	White	40
41 410	15x17 [IMQ]	White	40
41 413	30x17 [IMQ]	White	40
41 415	40x17 [IMQ]	White	40
41 416	60x17 [IMQ]	White	40
41 417	25x30 [IMQ]	White	40
41 419	40x30 [IMQ]	White	20
41 420	60x30 [IMQ]	White	20
01 452	20x10 [IMQ]	Grey	40
01 460	15x17 [IMQ]	Grey	40
01 463	30x17 [IMQ]	Grey	40
01 472	20x10 [IMQ]	Brown	40
01 480	15x17 [IMQ]	Brown	40
01 483	30x17 [IMQ]	Brown	40

Adjustable external corner

41 502	20x10 [IMQ]	White	40
41 504	30x10 [IMQ]	White	40
41 506	40x10 [IMQ]	White	40
41 510	15x17 [IMQ]	White	40
41 513	30x17 [IMQ]	White	40
41 515	40x17 [IMQ]	White	40
41 516	60x17 [IMQ]	White	40
41 517	25x30 [IMQ]	White	40
41 519	40x30 [IMQ]	White	20
41 520	60x30 [IMQ]	White	20
01 552	20x10 [IMQ]	Grey	40
01 560	15x17 [IMQ]	Grey	40
01 563	30x17 [IMQ]	Grey	40
01 572	20x10 [IMQ]	Brown	40
01 580	15x17 [IMQ]	Brown	40
01 583	30x17 [IMQ]	Brown	40

Mini-trunkings

Equipped mini-trunkings

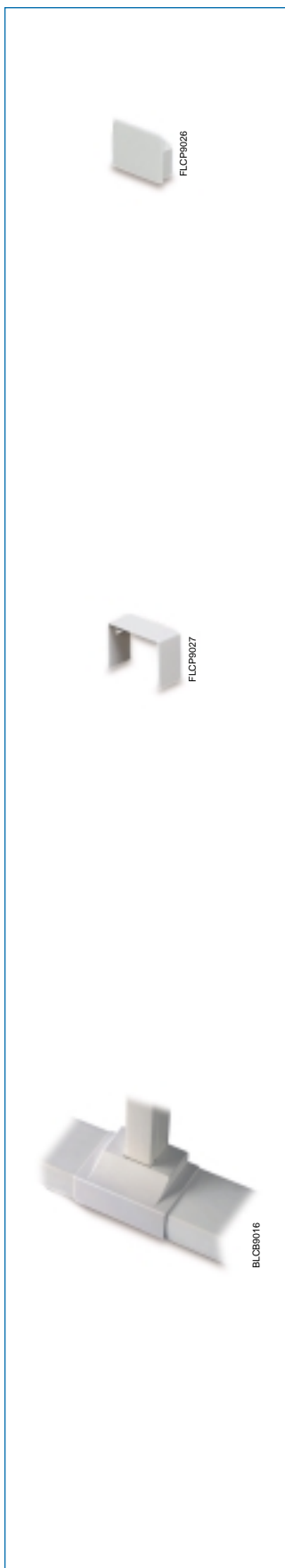

Article	Trunking dimensions WxH (mm)	Colour	Unit/pack – pieces
---------	------------------------------	--------	--------------------

End cap

41 602	20x10 [IMQ]	White	40
41 604	30x10 [IMQ]	White	40
41 606	40x10 [IMQ]	White	40
41 610	15x17 [IMQ]	White	40
41 613	30x17 [IMQ]	White	40
41 615	40x17 [IMQ]	White	40
41 616	60x17 [IMQ]	White	40
41 617	25x30 [IMQ]	White	40
41 619	40x30 [IMQ]	White	40
41 620	60x30 [IMQ]	White	40
01 652	20x10 [IMQ]	Grey	40
01 660	15x17 [IMQ]	Grey	40
01 663	30x17 [IMQ]	Grey	40
01 672	20x10 [IMQ]	Brown	40
01 680	15x17 [IMQ]	Brown	40
01 683	30x17 [IMQ]	Brown	40

Flat joint

41 702	20x10 [IMQ]	White	40
41 704	30x10 [IMQ]	White	40
41 706	40x10 [IMQ]	White	40
41 710	15x17 [IMQ]	White	40
41 713	30x17 [IMQ]	White	40
41 715	40x17 [IMQ]	White	40
41 716	60x17 [IMQ]	White	40
41 717	25x30 [IMQ]	White	40
41 719	40x30 [IMQ]	White	40
41 720	60x30 [IMQ]	White	40
01 752	20x10 [IMQ]	Grey	40
01 760	15x17 [IMQ]	Grey	40
01 763	30x17 [IMQ]	Grey	40
01 772	20x10 [IMQ]	Brown	40
01 780	15x17 [IMQ]	Brown	40
01 783	30x17 [IMQ]	Brown	40

Wall/ceiling tee branch connection

41 902	20x10 [IMQ]	White	20
41 904	30x10 [IMQ]	White	10
41 906	40x10 [IMQ]	White	10
41 910	15x17 [IMQ]	White	20
41 913	30x17 [IMQ]	White	10
41 915	40x17 [IMQ]	White	10
41 916	60x17 [IMQ]	White	10
41 917	25x30 [IMQ]	White	10
41 919	40x30 [IMQ]	White	10
41 920	60x30 [IMQ]	White	10
01 930	20x10 [IMQ]	Grey	20
01 932	15x17 [IMQ]	Grey	20
01 934	30x17 [IMQ]	Grey	10
01 940	20x10 [IMQ]	Brown	20
01 942	15x17 [IMQ]	Brown	20
01 944	30x17 [IMQ]	Brown	10

Mini-trunkings

Accessories for equipped mini-trunkings

2



Article	Trunking height (mm)	Colour	Unit/pack – pieces
---------	----------------------	--------	--------------------

Box for flat branch connections

Complete with circuit separator

41 800	10 – 17 [IMQ]	White	1/60
41 803	10 – 17 – 30 [IMQ]	White	1/40
01 802	10 – 17 [IMQ]	Grey	1/60
01 804	10 – 17 – 30 [IMQ]	Grey	1/40
01 801	10 – 17 [IMQ]	Brown	1/60
01 805	10 – 17 – 30 [IMQ]	Brown	1/40

Article	Description (mm)	Colour	Unit/pack- pieces
---------	------------------	--------	-------------------

Italian standard switch-socket floor box

For 2 Vimar 8000 series or Bticino Magic devices with supplied adapter.

Side trimmings for H 10 and H 17 mini-trunkings (except for 60x17).

41 806	2 devices [IMQ]	White	1/60
01 808	2 devices [IMQ]	Grey	1/60
01 810	2 devices [IMQ]	Brown	1/60
41 818	Inter. 60 mm [IMQ]	White	1/20
01 820	Inter. 60 mm [IMQ]	Grey	1/20
01 821	Inter. 60 mm [IMQ]	Brown	1/20

Article	Device	Modules	Mounting	Colour	Unit/pack-pieces
---------	--------	---------	----------	--------	------------------

French standard switch-socket box

For 1/2 Galion and Mosaic type devices. Side trimmings for H 10, H 17 and H 30 mini-trunkings.

41 840	Galion	1	Horizontal	White	1/60
41 842	Galion	1	Vertical	White	1/60
41 844	Galion	2	Horizontal	White	1/60
41 846	Mosaic	2	Horizontal/Vertical	White	1/60

Spanish standard switch-socket box

For 2 and 4 Stylo type devices. Side trimmings for H 10, H 17 and H 30 mini-trunkings.

41 850	Stylo	2	Horizontal/Vertical	White	1/16
41 854	Stylo	4	Horizontal	White	1/60

Italian standard telephone socket box

For fitting a unified telephone socket.

Side trimmings for H 10 and H 17 mini-trunkings (except for 60x17).

41 812	Telephone socket [IMQ]	White	1/60
01 814	Telephone socket [IMQ]	Grey	1/60
01 816	Telephone socket [IMQ]	Brown	1/60

Switch-socket floor boxes and telephone socket boxes must be installed at a minimum height of 175 mm from the axis at which the socket is inserted at floor level, in compliance with CEI 64-8 Standard

Frame for flush-mounting box

For branch connection with H 10 mm mini-trunking. Attached onto flush-mounting switch-socket box using 2 screws (supplied).

41 829	Inter-axis 83.5	White	1/10
--------	-----------------	-------	------

Mini-trunkings

Accessories for equipped mini-trunkings



FLCP9128



FLCP9032



FLCP9033

Article	Description (mm)	Colour	Unit/pack- pieces
---------	------------------	--------	-------------------

Switch-socket box

Side trimmings for H 10, 17 and 30 mini-trunkings.

For fitting a telephone socket on box with 83.5 interaxis use cover supplied separately (art. 42 112).

Box for 2 devices (or fasteners)

42 096	Inter. 60/67 mm [IMQ]	White	1/30
02 099	Inter. 60/67 mm [IMQ]	Grey	1/30
02 098	Inter. 60/67 mm [IMQ]	Brown	1/30

Box for 3 devices depth 43 mm

41 823	Inter. 83.5 mm [IMQ]	White	1/28
01 826	Inter. 83.5 mm [IMQ]	Grey	1/28
01 828	Inter. 83.5 mm [IMQ]	Brown	1/28

Box for 3 devices depth 53 mm

41 822	Inter. 83.5 mm [IMQ]	White	1/24
01 825	Inter. 83.5 mm [IMQ]	Grey	1/24
01 827	Inter. 83.5 mm [IMQ]	Brown	1/24

Box for 4 devices

41 830	Inter. 108 mm [IMQ]	White	1/20
01 831	Inter. 108 mm [IMQ]	Grey	1/20
01 832	Inter. 108 mm [IMQ]	Brown	1/20

Cover- interaxis 83.5 mm

Attached onto switch-socket box with 2 screws.

42 112	Telephone socket [IMQ]	White	20
42 122	Plain cover [IMQ]	White	20

Coupler for mini-trunkings

In self-extinguishing thermoplastic.

Used with watertight equipment and boxes (see catalogue 604211).

Degree of protection IP40.

45 965	With Ø 20 mm - 15x17 mm [IMQ]	White	20
45 966	With Ø 25 mm - 15x17-25x30 mm [IMQ]	White	20
45 967	With Ø 32 mm - 15x17-25x30-40x30 mm [IMQ]	White	20
45 968	With Ø 20 mm - 20x10-30x10 mm [IMQ]	White	20
45 969	With Ø 25 mm - 30x10-40x10 mm [IMQ]	White	20
05 960	With Ø 20 mm - 15x17 mm [IMQ]	Grey	20
05 963	With Ø 20 mm - 20x10-30x10 mm [IMQ]	Grey	20