

Low Voltage Products

OTP20GB 06_01
1SCC340002K1801

Plastic enclosed switches and safety switches now available also for M50 cable glands



Enclosure size: 200x400x140mm (w x h x d)
Cable outlets / side: 2xM50+M16
In safety switches auxiliary contacts included: 1 N.O.
Compression glands have to be ordered separately

Ordering information

Safety switches

Max. motor output [kW]				Type	Order number
230V AC-23A	400V AC-23A	500V AC-23A	690V AC-23A		
22	37	37	37	OTP 75T3M	1SCA022812R2890
22	45	45	45	OTP 90T3M	1SCA022812R2970
22	37	37	37	OTP 75T4M	1SCA022812R3010
22	45	45	45	OTP 90T4M	1SCA022812R3190
22	37	37	37	OTP 75T6M	1SCA022812R3270
22	45	45	45	OTP 90T6M	1SCA022812R3350
22	37	37	37	OTP 75A3M	1SCA022812R3430
22	45	45	45	OTP 90A3M	1SCA022812R3510
22	37	37	37	OTP 75A4M	1SCA022812R3780
22	45	45	45	OTP 90A4M	1SCA022812R3860
22	37	37	37	OTP 75A6M	1SCA022812R3940
22	45	45	45	OTP 90A6M	1SCA022812R4080

EMC- safety switches

22	37	37	37	OTE 75T3M	1SCA022812R4160
22	45	45	45	OTE 90T3M	1SCA022812R4240
22	37	37	37	OTE 75T4M	1SCA022812R4670
22	45	45	45	OTE 90T4M	1SCA022812R5050
22	37	37	37	OTE 75T6M	1SCA022812R5720
22	45	45	45	OTE 90T6M	1SCA022812R5810
22	37	37	37	OTE 75A3M	1SCA022812R5990
22	45	45	45	OTE 90A3M	1SCA022812R6020
22	37	37	37	OTE 75A4M	1SCA022812R6370
22	45	45	45	OTE 90A4M	1SCA022812R6450
22	37	37	37	OTE 75A6M	1SCA022812R6700
22	45	45	45	OTE 90A6M	1SCA022812R6880

Enclosed switches

Rated operational current [A]			Type	Ordering number
AC-22A ≤ 500V	AC-23A ≤ 415V	AC-23A 500V		
125	90	70	OTP125B3M	1SCA022812R7180
125	90	70	OTP125B4M	1SCA022812R7260
125	90	70	OTP125B6M	1SCA022812R7340
125	90	70	OTP125BA3M	1SCA022812R7420
125	90	70	OTP125BA4M	1SCA022812R7510
125	90	70	OTP125BA6M	1SCA022812R7690

Compression glands

Thread	Cable DIA [mm]	Type	Order number
M16	4.5-10	-ESKV 16	1SCA022715R5930
M50	18-35	-ESKV 50	1SCA022715R6400

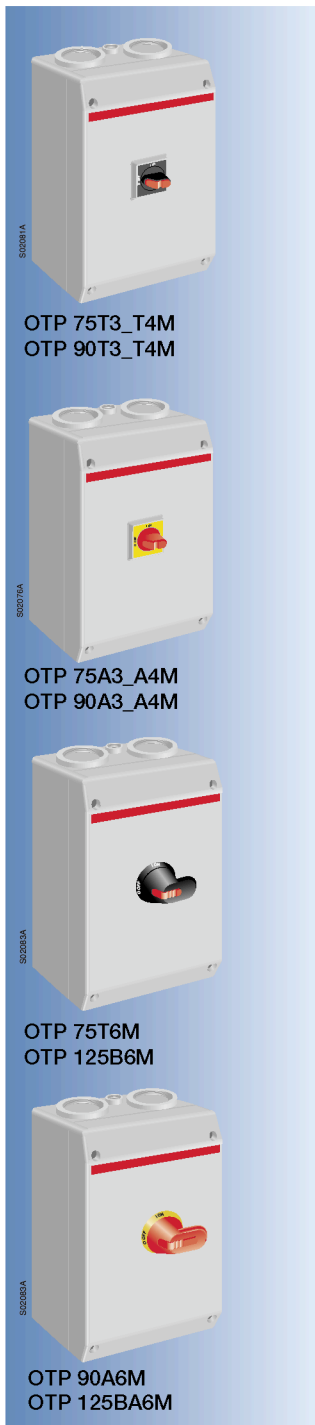


ABB Oy

Low Voltage Products
P.O. Box 622
FI-65101 VAASA, Finland

Telephone +358 10 22 4000
Telefax +358 10 22 45708
www.abb.com/lvswitches

